


UNMDU-BKT-CDM1 Panel Installation

General

The **Uniprise®** UNMDU-BKT-CDM1 panel (CC0062141) consists of a 3-inch (76 mm) high stackable mounting bracket, which can accommodate three copper voice or data modules and includes snap-in fasteners. The panel is designed to install in the UNMDU enclosure.

How to Contact Us

- To find out more about **CommScope® Uniprise** Solutions, visit us on the web at <http://www.commscope.com/>
- For customer support regarding **Uniprise** products, contact your local account representative or call 1-800-544-1948 or (828) 459-5000.

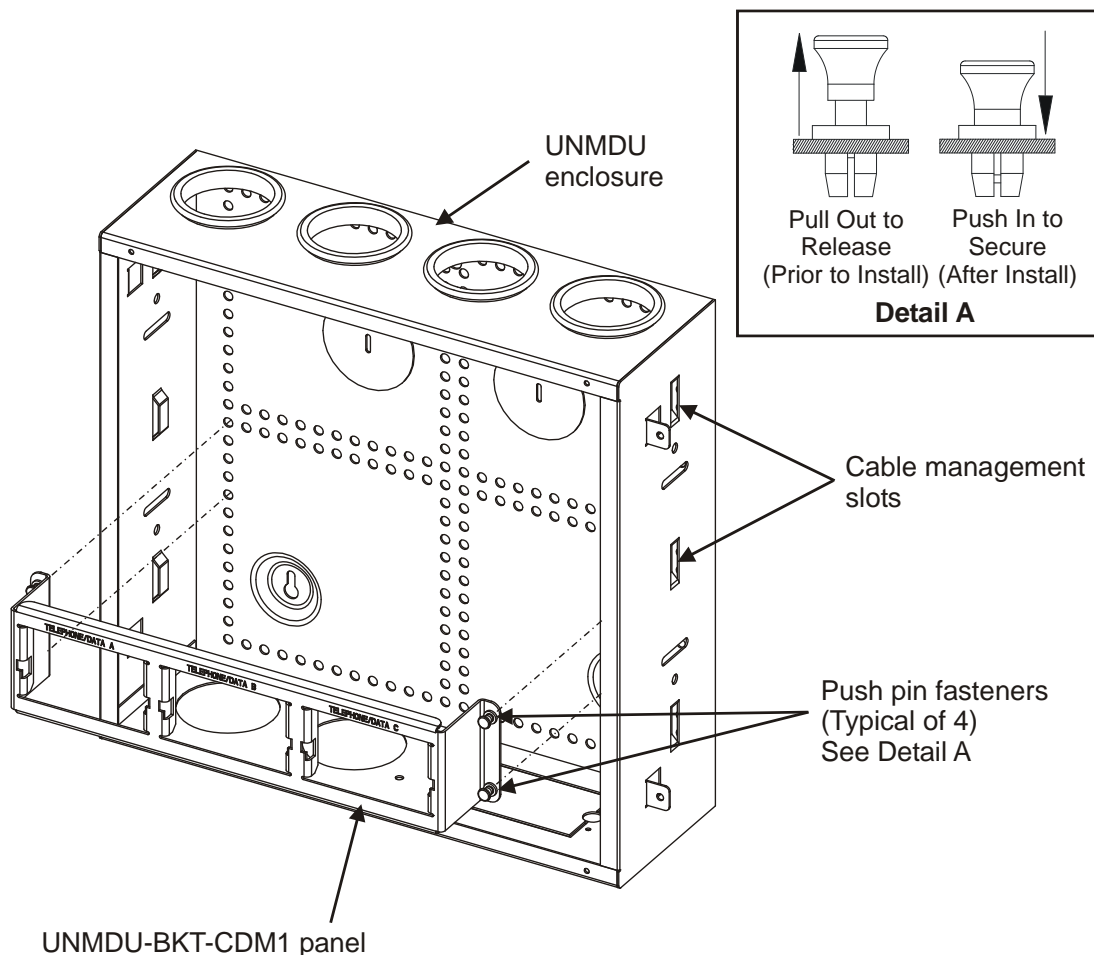

Parts List

Verify contents from the parts listed below:

Quantity	Description
1	3-inch (76 mm) high panel
1	Installation sheet

Installation

1. Make sure push pin fasteners are in the “open” position prior to installing panel into enclosure. See “Detail A” on previous page.
2. Select a mounting position that will be convenient to cable connections and other installed equipment. Locate panel within reach of cable connections. Install multiple panels starting with the lower position and continue up.

Note: The panel may be installed horizontally (as shown) or vertically on either the left or right side of the enclosure. You may install panel in top-most slots in the UNMDU enclosure; however, rear IDC field access is restricted in this location and will require removal of module from panel to terminate cables. It is recommended to install panel in second set of slots from top to take advantage of panel support for terminating cable on back of module.

3. Secure panel in place by locking push pin fasteners as shown in “Detail A”.
4. Secure cables using cable ties inserted through the cable management slots provided at sides of enclosure.

This product is covered by one or more of the following U.S. patents or their foreign equivalents:
6,362,430, 6,222,124.