


Network and Server Cabinet Adjustable Rail Positions

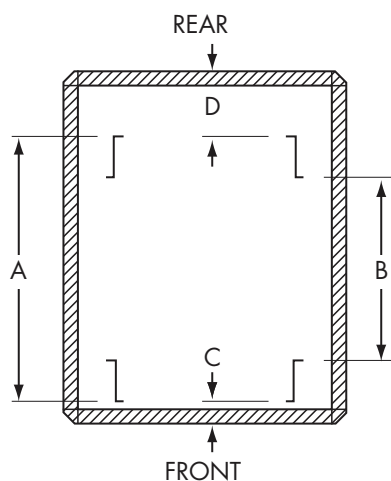

Dim A – Dimension between 19 in mounting surfaces on Front and Rear
 Dim B – Dimension between 25 mm mounting flange on Front and Rear
 Dim C – Dimension between 19 in mounting surface and inside of Front or Rear doors
 Dim D – Dimension between 19 in mounting surface and inside of Rear door

| | Factory Position | Minimum ¹ | Maximum ² |
|-----------------------------|------------------|----------------------|----------------------|
| 32 in (800) mm Depth | | | |
| Dim A | 25.3 in (642 mm) | 9.4 in (238 mm) | 28.2 in (715 mm) |
| Dim B | 16.1 in (410 mm) | 0.3 in (5.8 mm) | 19.0 in (483 mm) |
| Dim C | 2.6 in (66 mm) | 1.6 in (41 mm) | 1.6 in (41 mm) |
| Dim D | 3.5 in (89 mm) | 20.4 in (518 mm) | 1.6 in (41 mm) |

| | | | |
|------------------------------|------------------|------------------|------------------|
| 40 in (1000) mm Depth | | | |
| Dim A | 29.2 in (742 mm) | 9.4 in (238 mm) | 36.0 in (915 mm) |
| Dim B | 20.1 in (510 mm) | 0.3 in (5.8 mm) | 26.9 in (683 mm) |
| Dim C | 2.6 in (66 mm) | 1.6 in (41 mm) | 1.6 in (41 mm) |
| Dim D | 7.4 in (189 mm) | 28.3 in (718 mm) | 1.6 in (41 mm) |

| | | | |
|------------------------------|------------------|------------------|-------------------|
| 48 in (1200) mm Depth | | | |
| Dim A | 29.2 in (742 mm) | 9.4 in (238 mm) | 43.9 in (1114 mm) |
| Dim B | 20.1 in (510 mm) | 0.3 in (5.8 mm) | 34.7 in (882 mm) |
| Dim C | 2.6 in (66 mm) | 1.6 in (41 mm) | 1.6 in (41 mm) |
| Dim D | 15.3 in (389 mm) | 36.1 in (918 mm) | 1.6 in (41 mm) |

¹ Minimum – Rails extended towards door in nearest position
² Maximum – Rails extended away from door in farthest position