

Security Cable

Catalog #S222SSTP

NEC/CEC: CMP(ETL) C(ETL)


CABLE CONSTRUCTION:

CENTER CONDUCTOR:
 22 AWG Stranded Bare Copper

INSULATION:
 Plenum PVC
 Nom. Wall: 0.009"
 Dia. over Insulation: 0.047"
 Black and Red

SHIELD:
 Aluminum Mylar Tape

JACKET:
 Gray PVC
 Dia. over Jacket: 0.127"
 Nominal Jacket Thickness: 0.015"

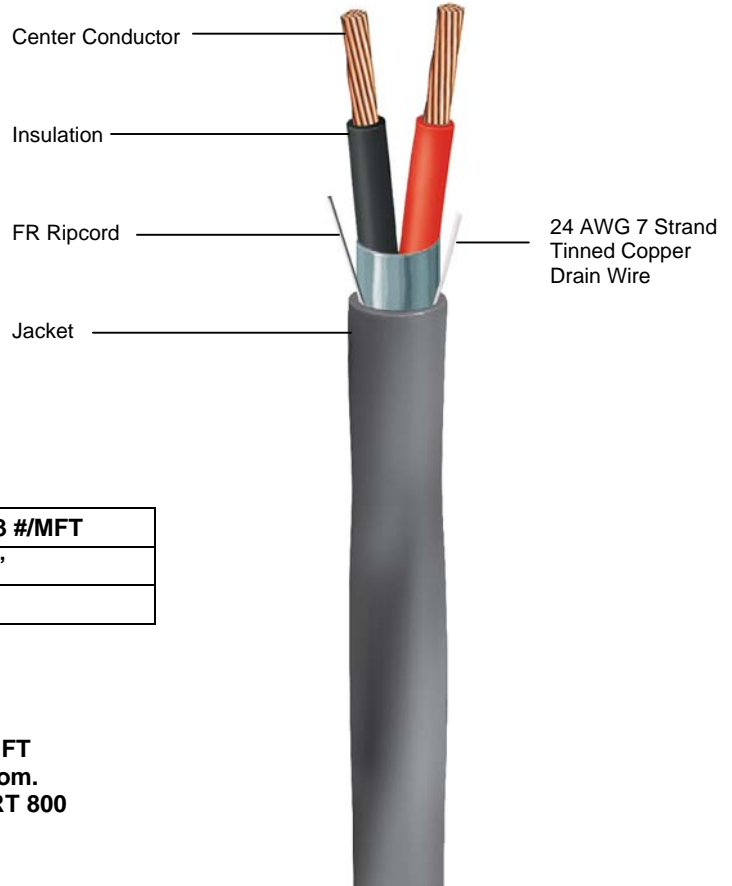

MECHANICAL SPECIFICATION

Cable Weight	11.3 #/MFT
Minimum Bend Radius	1.3"
Operation Temperature -20°C to 75°C	

ELECTRICAL PROPERTIES:

OPERATING VOLTAGE: 300 VRMS
MAX CONDUCTOR DCR: 17.0 Ohms/MFT
CAPACITANCE: 16.0 pF/Ft. Nom.
FLAME TEST: CMP NEC ART 800

FEATURES & BENEFITS:

Virgin materials
 Footage marking
 CMR per NEC Article 800
 Pure copper conductors
 Custom colors, print, lengths available
 (minimum order quantities apply)

APPLICATIONS:

Commercial audio
 Security systems
 Power limited controls
 Sound & audio
 Intercom/PA systems
 Broadcast
 Nurse call