

Security Cable

Catalog #S414USOR

NEC/CEC: FPLR(ETL)


CABLE CONSTRUCTION:

CENTER CONDUCTOR:
 14 AWG Solid Bare Copper

INSULATION:
 PVC
 Nom. Wall: 0.013"
 Dia. over Insulation: 0.090"
 Black, Red, Brown and Blue

SHIELD:
 UnShielded

JACKET:
 Red PVC
 Dia. over Jacket: 0.250"
 Nominal Jacket Thickness: 0.015"

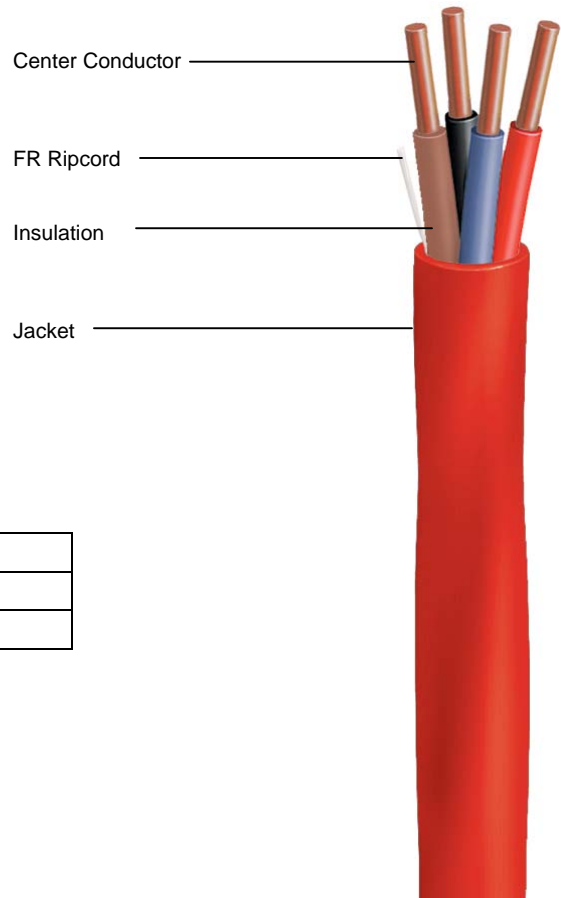

MECHANICAL SPECIFICATION

CABLE WEIGHT	66.00 #/MFT
MINIMUM BEND RADIUS	2.5"
OPERATION TEMPERATURE -20°C to 75°C	

ELECTRICAL PROPERTIES:

OPERATING VOLTAGE: 300 VRMS
 MAX CONDUCTOR DCR: 2.52 Ohms/MFT
 CAPACITANCE: 34.0 pF/Ft. Nom.
 FLAME TEST: FPLR NEC ART 760

FEATURES & BENEFITS:

Virgin materials
 Footage marking
 FPLP per NEC Article 760
 Pure copper conductors
 Custom colors, print, lengths available
 (minimum order quantities apply)

APPLICATIONS:

Commercial audio
 Security systems
 Power limited controls
 Sound & audio
 Intercom/PA systems
 Broadcast
 Nurse call